





DISPLAY

-T1  
/2.6:B



VLT FC302 I/O CARD

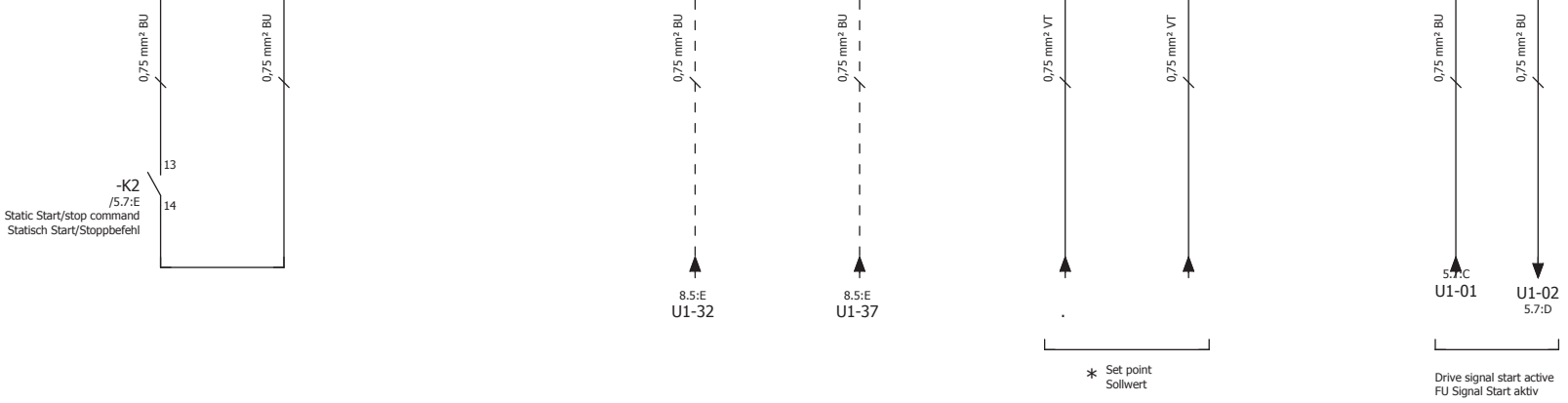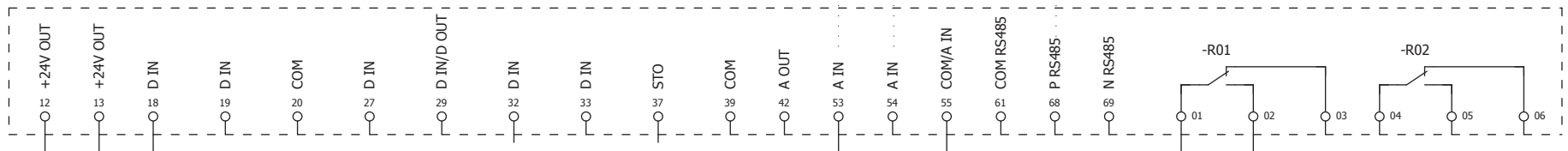

\* Set point  
Sollwert

Drive signal start active  
FU Signal Start aktiv

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

\* Current input, 0-20mA and 4-20mA  
Stromeingang, 0-20 mA und 4-20 mA  
Voltage input, -10 - +10 V DC  
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.
	9/30/2013		KARTHIK

Commission  
200KW VFD Panel  
Project description  
Disconnect switch+Fuse+dudt Filter  
Trennschalter+Sicherung+dudt Filter

Danfoss GmbH  
VLT Drives EMA, Carl-Legien Strasse 8  
33073 Offenbach, Germany



FILE-NAME:  
LOG08300.jpg  
Size 300px x 116px

Page description  
Frequency converter  
Frequenzumrichter

Project Number  
----  
SAP NO

= FC302  
+ N200KW 230V  
Manufacturer no