

A

B

C

D

E

F

A

B

C


D

E

F



DISPLAY

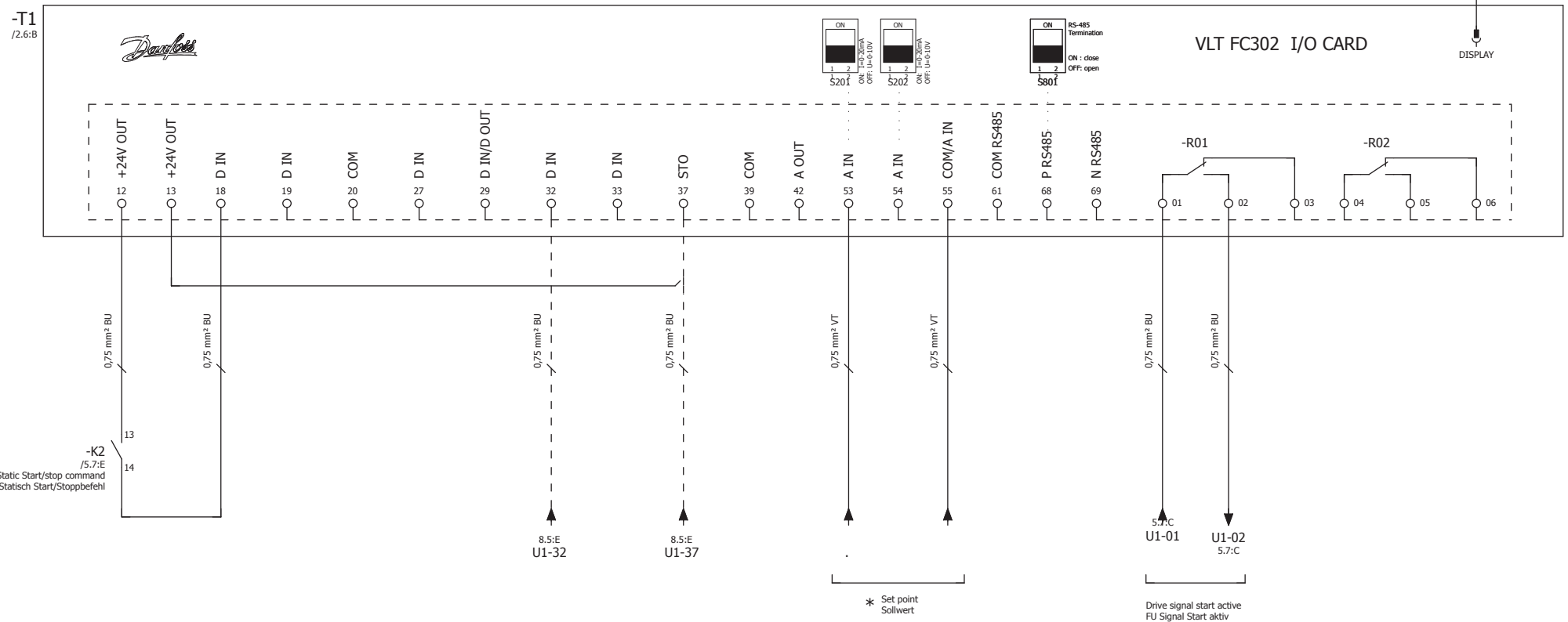

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

* Current input, 0-20mA and 4-20mA
Stromeingang, 0-20 mA und 4-20 mA
Voltage input, -10 - +10 V DC
Spannungseingang -10 - +10 V DC

5

7

Modification	Date	Name	Contr.	Date	9/30/2013
				Ed.	----
				Appr	----
				Contr.	----

Commission
200KW VFD Panel
Project description
Contactor+dudt Filter
Schütz+dudt Filter

Danfoss GmbH
VLT Drives EMA, Carl-Legien Strasse 8
63073 Offenbach, Germany



FILE-NAME:
LOGO8300.jpg
Size 300px x 116px

Page description
Frequency converter
Frequenzumrichter

Project Number

SAP NO

= FC302
+ N200KW 230V
Manufacturer no