




DISPLAY



-T1 /2.5:B

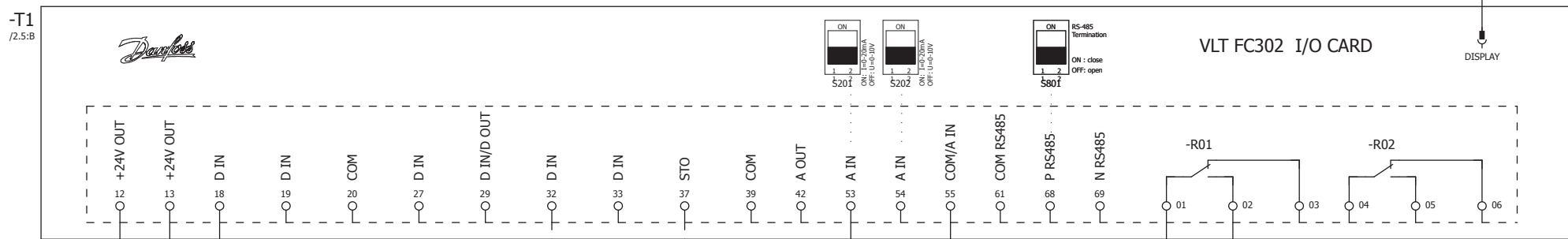

VLT FC302 I/O CARD

-K2 /5.7:E Static Start/stop command Statisch Start/Stoppbefehl

* Set point Sollwert

Drive signal start active FU Signal Start aktiv

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

* Current input, 0-20mA and 4-20mA Stromeingang, 0-20 mA und 4-20 mA
Voltage input, -10 - +10 V DC Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.

Commission	9/30/2013	315KW VFD Panel
Ed.	----	Project description
Appr	----	Disconnect switch
		Trennschalter

Danfoss GmbH
VLT Drives EMA, Carl-Legien Strasse 8
63073 Offenbach, Germany



FILE-NAME:
LOG08300.jpg
Size 300px x 116px

Page description
Frequency converter
Frequenzumrichter

Project Number	----
SAP NO	

= FC302
+ P315KW 230V
Manufacturer no