


-T1  
/2.6:B



DISPLAY

VLT FC302 I/O CARD

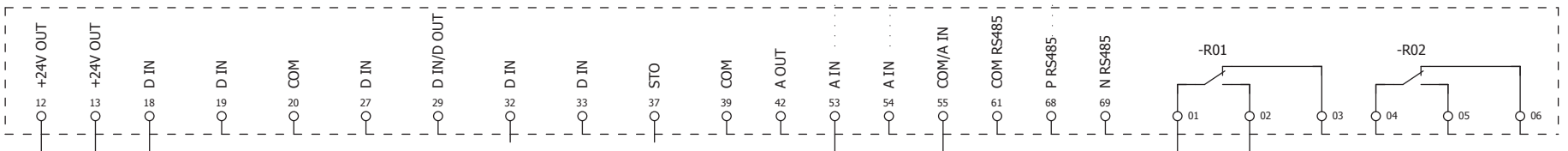

-K2  
/5.7:E  
Static Start/stop command  
Statisch Start/Stoppbefehl



\* Set point Sollwert

Drive signal start active  
FU Signal Start aktiv

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

\* Current input, 0-20mA and 4-20mA  
Stromeingang, 0-20 mA und 4-20 mA  
Voltage input, -10 - +10 V DC  
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.	Date	9/30/2013
				Ed.	----
				Appr	----

Commission  
**90KW VFD Panel**  
Project description  
Contactor+dudt Filter  
Schütz+dudt Filter

Danfoss GmbH  
VLT Drives EMA, Carl-Legien Strasse 8  
63073 Offenbach, Germany



FILE-NAME:  
LOG08300.jpg  
Size 300px x 116px

Page description  
Frequency converter  
Frequenzumrichter

Project Number	-----	Project description	= FC302 + N90KW 230V
SAP NO	-----	Manufacturer no	-----