




-U1  
/2.5:B

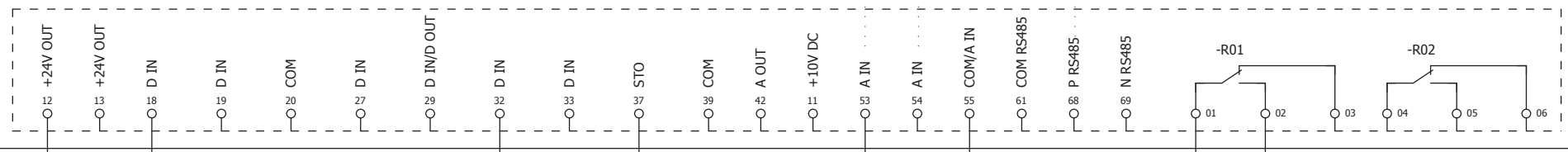

### VLT FC302 I/O CARD



0,75 mm² BU

0,75 mm² BU

0,75 mm² BU

0,75 mm² BU

0,75 mm² VT

0,75 mm² VT

0,75 mm² BU

0,75 mm² BU

-K2  
/4.7:E  
Start/stop command  
Start/Stopbefehl

13

14

7.5:E  
U1-32

7.5:E  
U1-37

\* Set point  
Sollwert

Drive signal start active [123]  
FU Signal Start aktiv [123]

\* Current input, 0-20mA and 4-20mA  
Stromeingang, 0-20 mA und 4-20 mA  
Voltage input, -10 - +10 V DC  
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.	KARTHIK
			Ed.	RAMKUMAR
			Appr	FALKO
			Date	9/30/2013

Commission  
200KW VFD Panel  
Project description  
Contactor+Fuse

Danfoss GmbH  
VLT Drives EMA, Carl-Legien Strasse 8  
63073 Offenbach, Germany



FILE-NAME:  
LOG08300.jpg  
Size 300px x 116px

Page description  
Frequency converter  
Frequenzumrichter

Project Number  
MC\_ - - - - -  
SAP NO

= FC302  
+ N200KW 230V  
Manufacturer no