 









-U1
/2.5:B

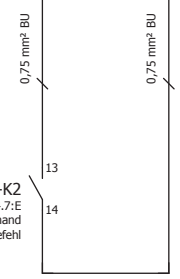


VLT FC302 I/O CARD

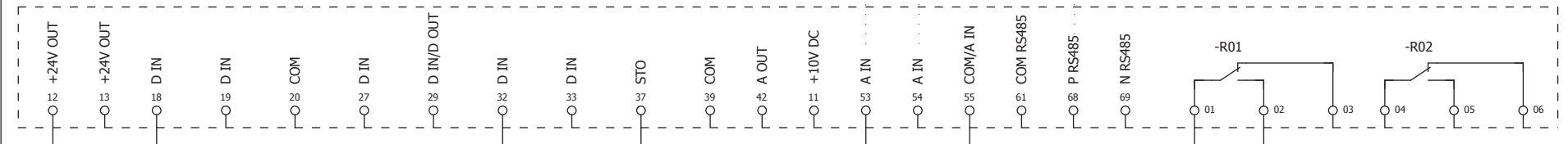

 -K2
/4.7:E
Start/stop command
Start/Stoppbefehl

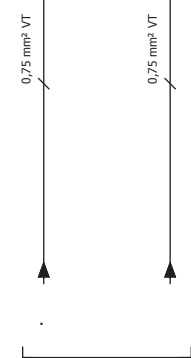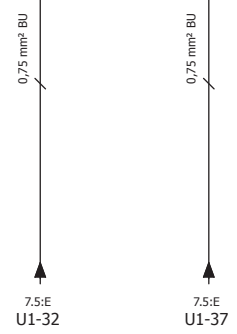

* Set point
Sollwert

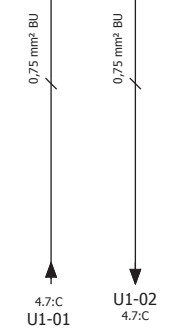

Drive signal start active [123]
FU Signal Start aktiv [123]

* Current input, 0-20mA and 4-20mA
Stromeingang, 0-20 mA und 4-20 mA
Voltage input, -10 - +10 V DC
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.	KARTHIK	Commission	90KW VFD Panel Project description	Danfoss GmbH VLT Drives EMA, Carl-Legien Strasse 8 63073 Offenbach, Germany		FILE-NAME: LOG08300.jpg Size 300px x 116px	Page description Frequency converter Frequenzumrichter	Project Number MC_ - - - - - SNP NO	= FC302 + N90KW 230V Manufacturer no	Page 5 Page 32